

***PT Select***



**PT SELECT MOUNTED  
SPHERICAL ROLLER BEARINGS**  
A TRUSTED, COMPETITIVE SOLUTION



**RegalRexnord™**

# Let Our Bearing Offering Make Your Job Easier

## PROVEN BEARING QUALITY

We understand the high quality of your bearing designs is critical to uptime, so it's critical to us. That's why we test every bearing that leaves our facility before it ships to you.

- Product qualification process through custom-built, state-of-the-art testing confirms the bearing's quality and reliability
- Spin testing under load ensures against defects to the rollers or raceway, eliminating the potential for bearing "chatter" after installation
- All printed performance values validated through laboratory testing at the Regal Rexnord™ Innovation Center, an independent, accredited laboratory
- **Backed by our standard Regal Rexnord warranty, with optional two-year warranty by registering on [Rexnord.com](http://Rexnord.com)**



*Spin testing under load ensures against defects to each bearing's rollers or raceway.*

## NEW ONLINE TOOLS

- Efficient e-commerce experience with real-time inventory availability, online order tracking, and more
- Online hassle-free bearing selection and ordering
- Exclusive QR code on your bearings for instant access to critical documents
- Free Rexnord® Connect™\* app for competitive interchange guides, videos, and more
- Free Augment app available for download to experience our bearings in 3D

## OFF-THE-SHELF SOLUTIONS WITH QUICK TURNAROUND


We designed PT Select to meet customer's quality, delivery and availability needs.

- Designed with state of the art technology, and decades of application knowledge that strike the perfect balance of durability and value for a wide range of off-the-shelf configurations
- The bearing you need is always in stock, providing fast order turnarounds
- Intuitive and user-friendly nomenclature

## ENGINEERED BEARING SEALS FOR INCREASED PRODUCT LIFE

Designed for efficiency, the bearing delivers the seal performance your environment requires.

- Standard triple lip and clearance seal provide maximum ingress protection against contaminants which are a leading cause of bearing failure
- Clearance seal reduces operating temperatures at higher speeds
- Features nitrile material with protective metal shield

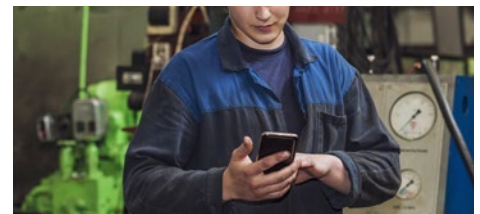

*Three points of contact (shown above) provide superior ingress protection against contaminants.*



\* Connect is believed to be the trademark and/or trade name of T-Mobile USA, Inc. and is not owned or controlled by Regal Rexnord Corporation or its affiliates.

## FEATURES & BENEFITS



QR code connects to installation, maintenance, technical, born on info plus one year extended warranty

Specialized geometry and materials that run cooler, vibrate less, and support heavier loads with a lighter housing

Drop-in replacement saves installation time and money

Triple lip seal provides best-in-class ingress protection and speed ratings for a wide variety of applications. Clearance seals also available

100% spin testing to ensure smooth concentric load distribution

## Additional Features & Benefits

- State-of-the-art housing design allows increased strength while optimizing material
- Industry-standard dimensions for interchangeability with leading brands
- Standard, off-the-shelf sizes for quick turnaround needs
- Rugged metal retainer for increased strength and durability
- Shaft ready and pre-lubricated with our standard grease for normal operation

## BEARING HOUSING STYLE OPTIONS



### 2-bolt Pillow Block

- Bore range: 1-7/16 – 3-15/16 in
- Optional clearance seal
- Expansion unit available



### 4-bolt Pillow Block

- Bore range: 1-15/16 – 4-7/16 in
- Optional clearance seal
- Expansion unit available
- 4-bolt Pillow Block – Type E available for 3-1/2 in bore size



### 2-bolt Pillow Block – Type E

- Bore range: 1-7/16 – 3-7/16 in
- Optional clearance seal
- Expansion unit available



### Flange Block

- Bore range: 1-7/16 – 3-15/16 in
- Optional clearance seal
- Expansion unit available



### Flange Block – Type E

- Bore range: 1-7/16 – 3-15/16 in
- Optional clearance seal
- Expansion unit available



### Piloted Flange

- Bore range: 1-7/16 – 4-7/16 in
- Optional clearance seal
- Expansion unit available

## KEY INDUSTRIES

Aggregate  
Air & Fluid Handling  
Cement  
Material Handling  
Package Handling

## KEY APPLICATIONS

Conveyors  
Fans and Blowers



## Nomenclature

Our bearings are consistent with industry standards and provide intuitive nomenclature, making your bearing selection and ordering process easier.

SYMBOL	DESCRIPTION	P2B - 107 - C E			
EFB	Type E Flanged Unit; 4-bolt square				
EP2B	Type E 2-Bolt Pillow Block				
EP4B	Type E 4-Bolt Pillow Block				
FB	Flanged Unit; 4-bolt square				
FC	Flanged Cartridge Unit; 4-bolt round				
P2B	2-Bolt Pillow Block				
P4B	4-Bolt Pillow Block				
107	1-7/16"				
111	1-11/16"				
115	1-15/16"				
203	2-3/16"				
207	2-7/16"				
208	2-1/2"				
211	2-11/16"				
215	2-15/16"				
307	3-7/16"				
308	3-1/2"				
315	3-15/16"				
407	4-7/16"				
T	Triple Lip Seal				
C	Clearance Seal				
Blank	Fixed				
E	Expansion				

## The Complete Regal Rexnord™ Roller Bearing Offering

Regal Rexnord customers have depended on our premium, quality roller bearing design, performance and technical support for decades. Unsure of which Regal Rexnord Bearing offering is right for your application?

- **PT Select Mounted Spherical Roller Bearings** for off-the-shelf reliability to make your job easier
- **Link-Belt® Roller Bearings** as your trusted workhorse for demanding applications
- **Rex® Roller Bearings** for custom-engineered solutions for specialized equipment



## PT Select

Motion Control Solutions  
Regal Rexnord

Contact us: [regalrexnord.com/contact](https://www.regalrexnord.com/contact)

[regalrexnord.com](https://www.regalrexnord.com)

The proper selection and application of products and components, including assuring that the product is safe for its intended use, are the responsibility of the customer. To view our Application Considerations, please visit <https://www.regalrexnord.com/Application-Considerations>. To view our Standard Terms and Conditions of Sale, please visit <https://www.regalrexnord.com/Terms-and-Conditions-of-Sale> (which may redirect to other website locations based on product family).

"Regal Rexnord" is not indicative of legal entity. Refer to product purchase documentation for the applicable legal entity. Regal Rexnord, Rexnord, PT Select, Link-Belt and Rex are trademarks of Regal Rexnord Corporation or one of its affiliated companies. © 2016, 2023 Regal Rexnord Corporation, All Rights Reserved. MCB23012E • Form# BR1-011E

**RegalRexnord**